


[See all 3 Products in Family](#)

OD 0.04 - 3.0, 50.8 x 25.4mm Stepped ND Filter

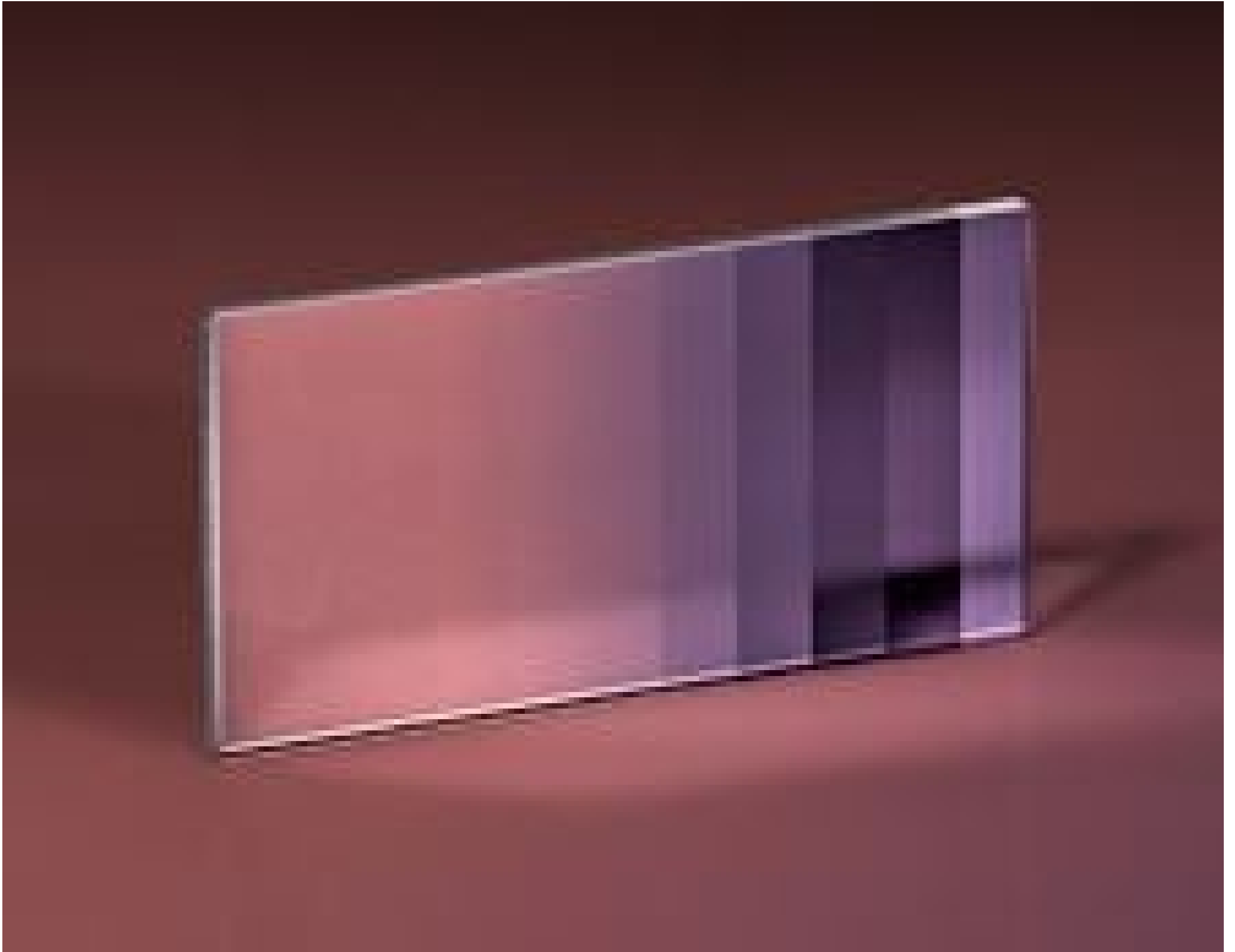

Stock **#64-384** **2 In Stock**

1 MRP ₹26,333

Price inclusive of all taxes

ADD TO CART

Volume Pricing	
Qty 1-10	₹26,333 each
Qty 11-25	₹23,710 each
Qty 26-49	₹22,599 each
Need More?	Request Quote

Product Downloads

General

Neutral Density Filter **Type:**

Physical & Mechanical Properties

25.4 x 50.8 **Dimensions (mm):**

2.0 **Length (inches):**

50.80 **Length (mm):**

0.062 **Thickness (inches):**

1.0 **Width (inches):**

25.40 **Width (mm):**

Optical Properties

0.04 - 3.0 **Optical Density OD (Average):**

Float Glass **Substrate:**

Stepped Variable **Coating:**

400 - 700 **Blocking Wavelength Range (nm):**

Regulatory Compliance

[View](#) **Certificate of Conformance:**

China **Country of Origin:**


Imported By:
Edmund Optics India Private Limited
267, Greystone Building, Second Floor,
6th Cross Rd, Binnamangala,
Stage 1, Indiranagar, Bengaluru,
Karnataka, India 560038
Phone: +91- 80-6845 0000

Product Details

- 11 Discrete Density Steps
- Design Wavelength of 400 - 700nm
- Density Neutrality of $\pm 5\%$

Density and transmission vary in eleven equal steps across the surface length. The steps are abrupt changes and no light escapes between them. Spectrally flat neutral density coating. Ideal for applications requiring variable densities and known density values.

Technical Information

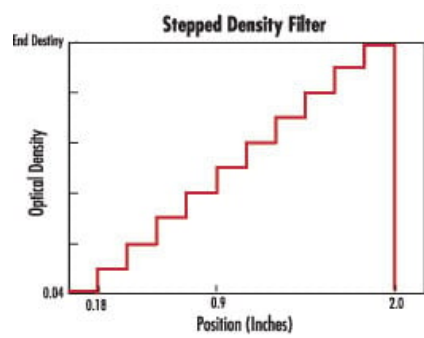

Compatible Mounts