


OD 0.04 - 4.0, 76.2 x 25.4mm, Continuously Variable ND Filter

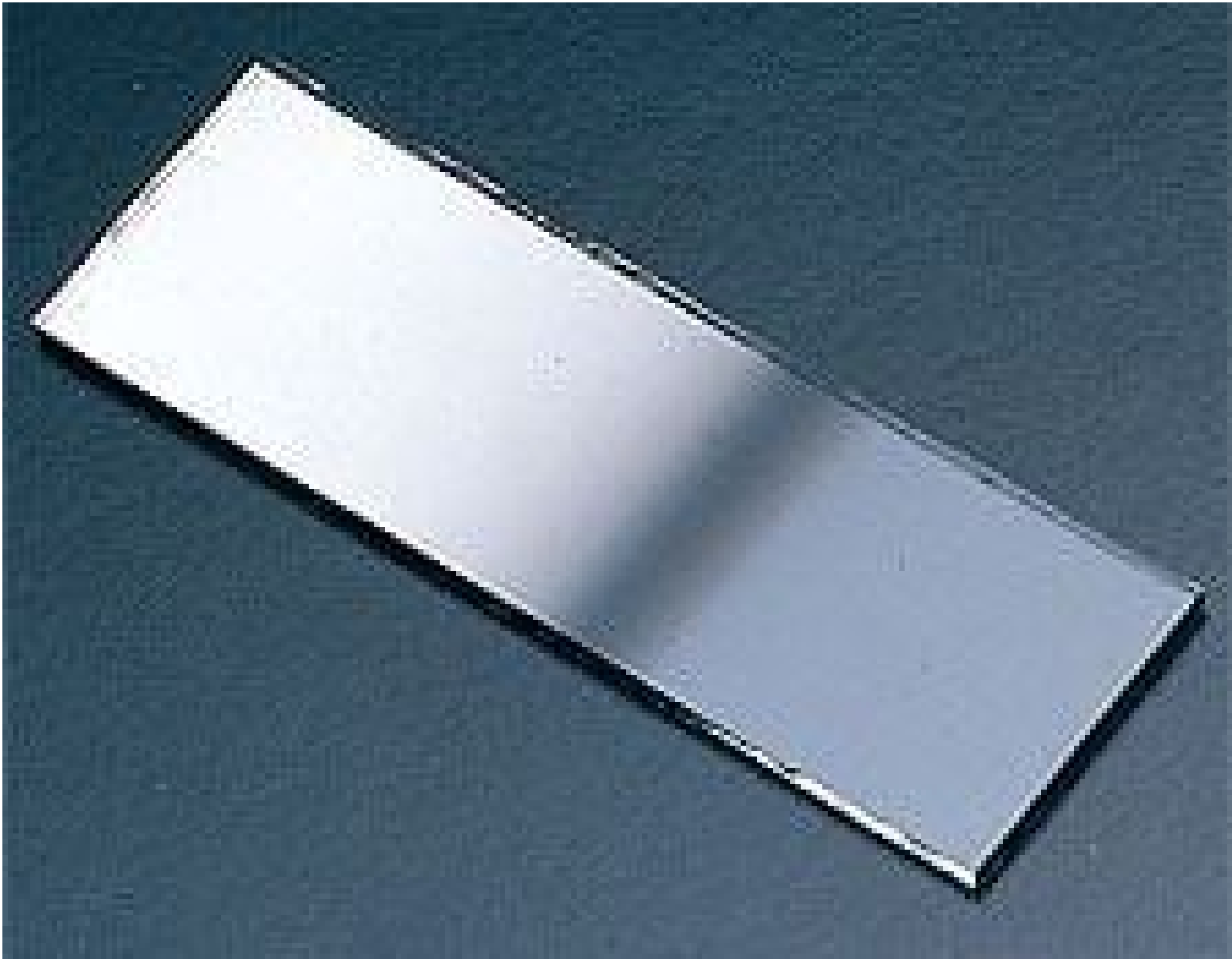

Stock #63-048 10 TO 12 DAYS

- 1 + ₹14,181.00

ADD TO CART

Qty 1-10	₹14,181.00
Qty 11+	₹12,763.00
Volume Pricing	Request Quote

Get Product Downloads

Dimensions (mm): 25.4 x 76.2
Angle of Incidence (°): 0.00
Optical Density OD (Average): 0.04 - 4.0

Substrate: ☐ Float Glass
Length (inches): 3.00
Length (mm): 76.20
Coating: Surface 1: Inconel
Thickness (inches): 0.063 ±0.01
Thickness (mm): 1.60 ±0.25
Type: Neutral Density Filter
Width (inches): 1.00
Width (mm): 25.40
Blocking Wavelength Range (nm): 400 - 700
Construction: Plate

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View