

[See all 14 Products in Family](#)

Olympus PLN 100X Oil Immersion Objective

See More by [Olympus](#)



#86-816

Stock **#86-816** **2 In Stock**

1 MRP ₹1,50,804

1 Price inclusive of all taxes

ADD TO CART

Volume Pricing

Qty 1+	₹1,50,804 each
Need More?	Request Quote

Product Downloads

General

Model Number:
PLN100XO

Compatible Tube Lens Focal Length (mm):
Focal Length: 180mm

Type:
Microscope Objective

Style:
Infinity Corrected

Olympus **Manufacturer:**

Recommended Immersion Oil [#86-834](#) **Note:**

Physical & Mechanical Properties

0.22 **Field of View (mm):**

44.70 **Length excluding Threads (mm):**

24 **Maximum Diameter (mm):**

114.0 **Weight (g):**

Optical Properties

N/A **Compatible Cover Glass Thickness (mm):**

1.80 **Focal Length FL (mm):**

100X **Magnification:**

1.25 **Numerical Aperture NA:**

0.27 **Resolving Power (μm):**

0.27 **Depth of Field (μm):**

0.15 **Working Distance (mm):**

22 **Field Number (mm):**

45 **Parfocal Length (mm):**

Oil **Immersion Liquid:**

1760 **Depth of Focus (μm):**

4.50 **Entrance Pupil Diameter (mm):**

Threading & Mounting

RMS / 20.32mm x 36 TPI **Mounting Threads:**

Regulatory Compliance

[View](#) **Certificate of Conformance:**

Japan **Country of Origin:**

Imported By:
Edmund Optics India Private Limited
267, Greystone Building, Second Floor,
6th Cross Rd, Binnamangala,
Stage 1, Indiranagar, Bengaluru,
Karnataka, India 560038
Phone: +91- 80-6845 0000


Product Details

- Ideal for Brightfield, Darkfield, or Fluorescence Microscopy
- Excellent Price-to-Performance Ratio
- Suitable for Introductory and Advanced Optical Microscopy Applications
- Additional [Olympus Infinity Corrected Objectives](#) Available


Olympus Plan Achromatic Objectives are designed for clinical laboratory or examination applications. When using brightfield observation in a transmitted illumination system, Olympus Plan Achromatic Objectives provide excellent field flatness of up to F.N.22.

Technical Information

#86-816

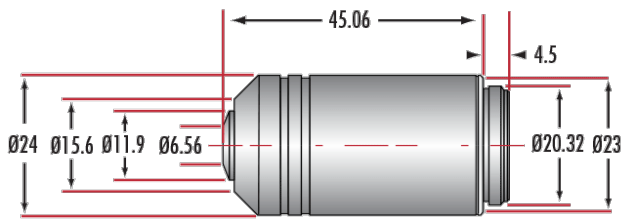

**Using Olympus Objectives
with C-Mount Cameras**

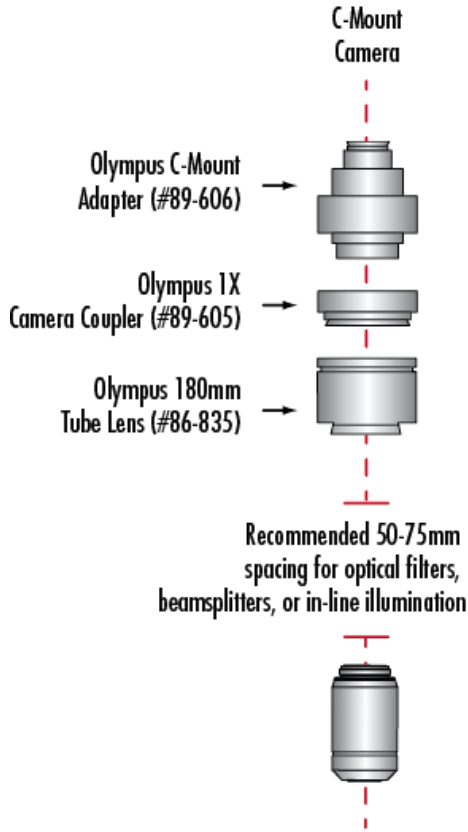

	Stock #	A	B	C	D	E	F	G
PLN 2X	16-879	39.1	3.4	0.0	16.8	16.8	24.0	4.5
PLN 4X	86-812	26.4	4.4	0.0	15.8	15.8	24.0	4.5
PLN 10X	86-813	34.3	4.1	1.6	10.5	16.0	24.0	4.5
PLN 20X	86-814	43.7	4.2	2.4	6.1	15.6	24.0	4.8
PLN 40X	86-815	44.3	4.2	3.0	7.5	15.6	24.0	4.5
PLN 100X	86-816	44.7	4.2	2.5	6.6	15.6	24.0	4.5

