


Pixelink PL-D722MU-T, 2/3" 2.3MP, C-Mount USB 3.0 Monochrome Camera

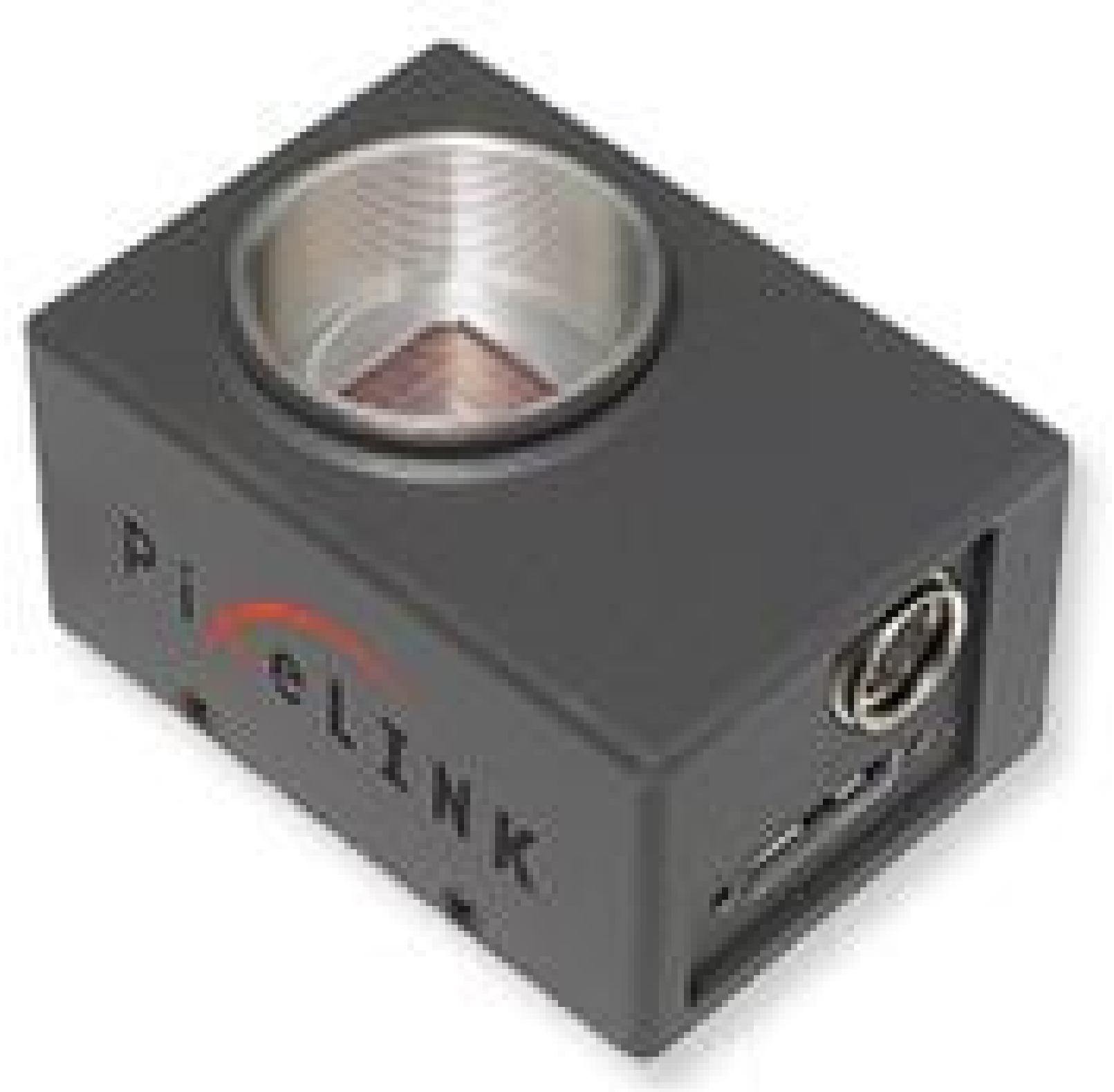

Pixelink® USB 3.0 Cameras (Full Housing)



Stock **#89-382** 10 TO 12 DAYS

[Similar Cameras](#)

- 1 +

₹138,765.00

ADD TO CART

Qty 1+
₹138,765.00

Volume Pricing
Request Quote

Note: This item requires accessories for use | [Learn More](#)

Get Product Downloads

Video Output:

USB 3.0

Type:

Monochrome Camera

Manufacturer:

Pixelink
Mounting Threads: 1/4-20 with Tripod Mount Adapter #89-408
Image Buffer: Not Specified
Camera Family: PL-D
Model Number: PL-D722MJ-T
Imaging Sensor: ON Semi VITA2000
Type of Sensor: Progressive Scan CMOS
Type of Shutter: Global
Camera Sensor Format: 2/3"
Resolution (MegaPixels): 2.30
Pixels (H x V): 1,920 x 1,200
Pixel Size, H x V (µm): 4.8 x 4.8
Sensing Area, H x V (mm): 9.22 x 5.76
Frame Rate (fps): 87.00
Pixel Depth: 8/10 bit
Exposure Time: 1µs - 4.33s
Connector: USB 3.0, Micro-B
Power Supply: Power over USB
Power Consumption (W): Not Specified
GPIOs: 1 opto-isolated trigger input, 1 opto-isolated output, 2 non-isolated outputs, 1 non-isolated input
Synchronization: Hardware Trigger (GPIO) or Software Trigger
Dimensions (mm): 55 x 38.5 x 27 (excludes connectors and lens mount)
Weight (g): 89
Mount: C-Mount
Housing: Full
Interface Port Orientation: Side Panel
Dynamic Range (dB): 53
Operating Temperature (°C): 0 to +50
Storage Temperature (°C): -45 to +85
GPIO Connector Type: 8-pin Hirose (HR25)
Machine Vision Standard: USB3 Vision v1.0
Operating System: Software Driver: Windows 32 and 64 bit

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View

