 



Hoya RT830 (IR) 25.4mm Dia., Colored Glass Bandpass Filter

See More by [Hoya](#)

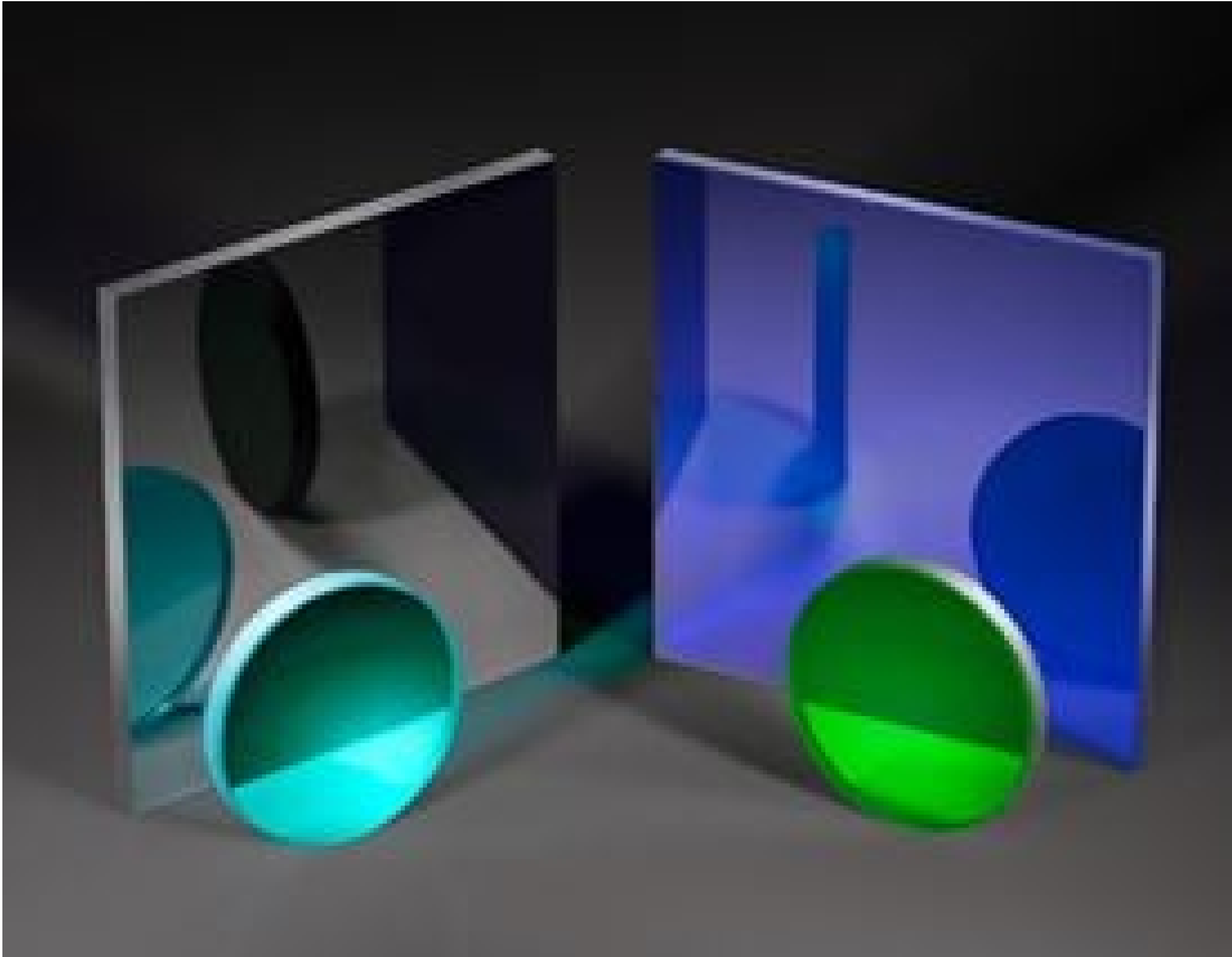

Stock **#46-443**

10 TO 12 DAYS

[Additional Bandwidths](#)

-

1

+

₹5,481.00

ADD TO CART

Qty 1-10
₹5,481.00
Qty 11+
₹4,872.00
Volume Pricing
Request Quote

Get Product Downloads



Diameter (mm):
25.40

Center Wavelength CWL (nm):

830.00
Density (g/cm³): 2.75
Full Width-Half Max FWHM (nm): 260.00
Glass/Filter Number: Hoya RT830
Substrate: ☐ Colored Glass
Coating: Uncoated
Color: Black
Surface Quality: 60-40
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.2
Type: Bandpass Filter
Wavelength: IR
Parallelism (arcmin): ≤1
Dimensional Tolerance (mm): +0/-0.25

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Compliant
Certificate of Conformance: View