


SCHOTT NG9, 4.0 OD, 25mm Dia., Absorptive ND Filter

See More by [SCHOTT Optical Components](#)

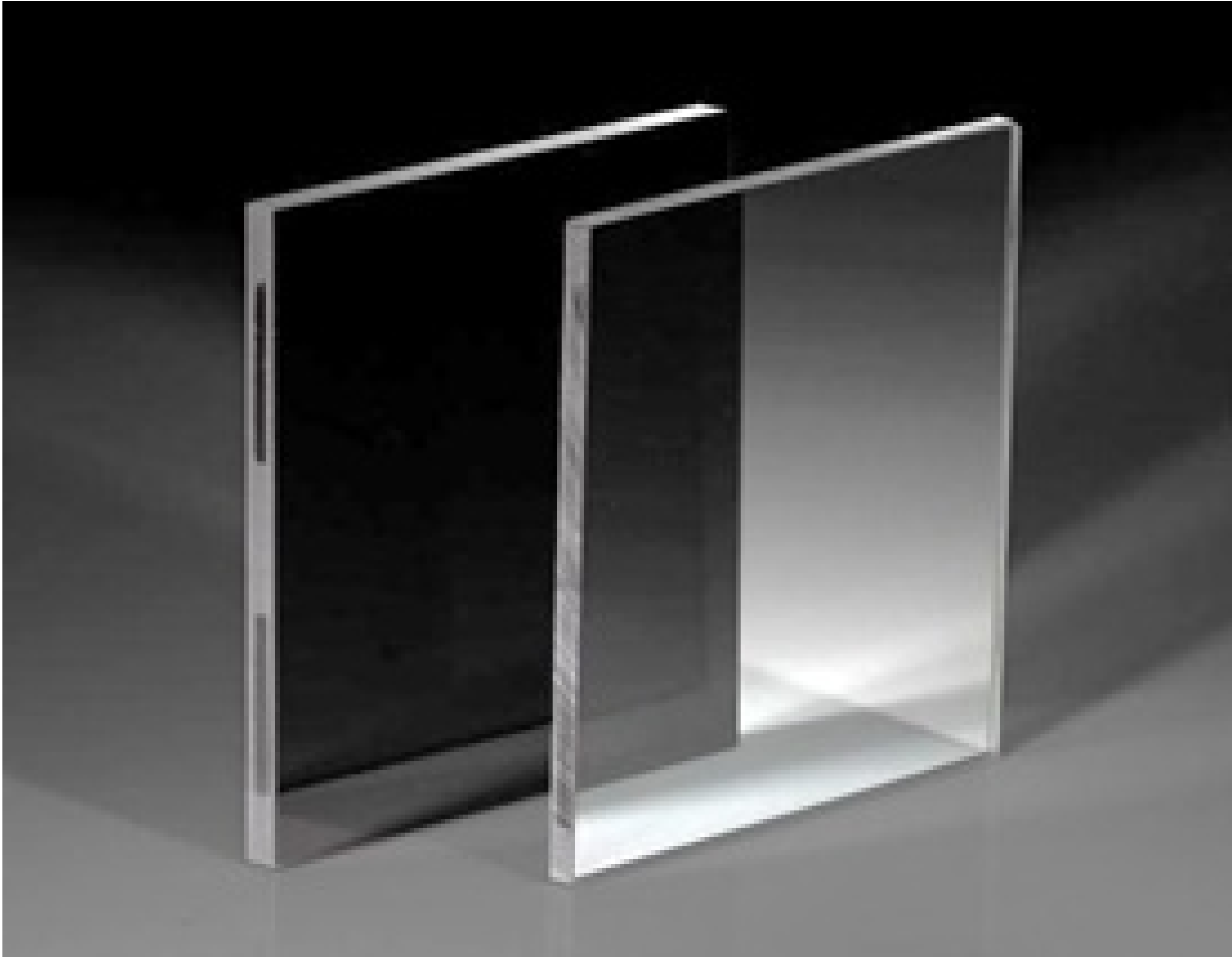

Stock #16-673 10 TO 12 DAYS

-

1

+

₹3,654.00

ADD TO CART

Qty 1-10
₹3,654.00
Qty 11+
₹3,219.00
Volume Pricing
Request Quote

Get Product Downloads

Diameter (mm):
25.00

Optical Density OD (Average):
4.0 ±0.07 @ 546nm

Glass/Filter Number:
[SCHOTT NG9](#)

Coating:

Uncoated
Index of Refraction n_d: 1.51
Surface Quality: 80-50
Transformation Temperature (°C): 470
Thickness (mm): 2.90
Thickness Tolerance (mm): (nominal)
Transmission (%): 0.010 ±0.0017% @ 546nm
Type: Neutral Density Filter
Dimensional Tolerance (mm): ±0.38
Wavelength Range (nm): 400 - 700

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View