 



SCHOTT VG20, 50mm Sq., 3mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

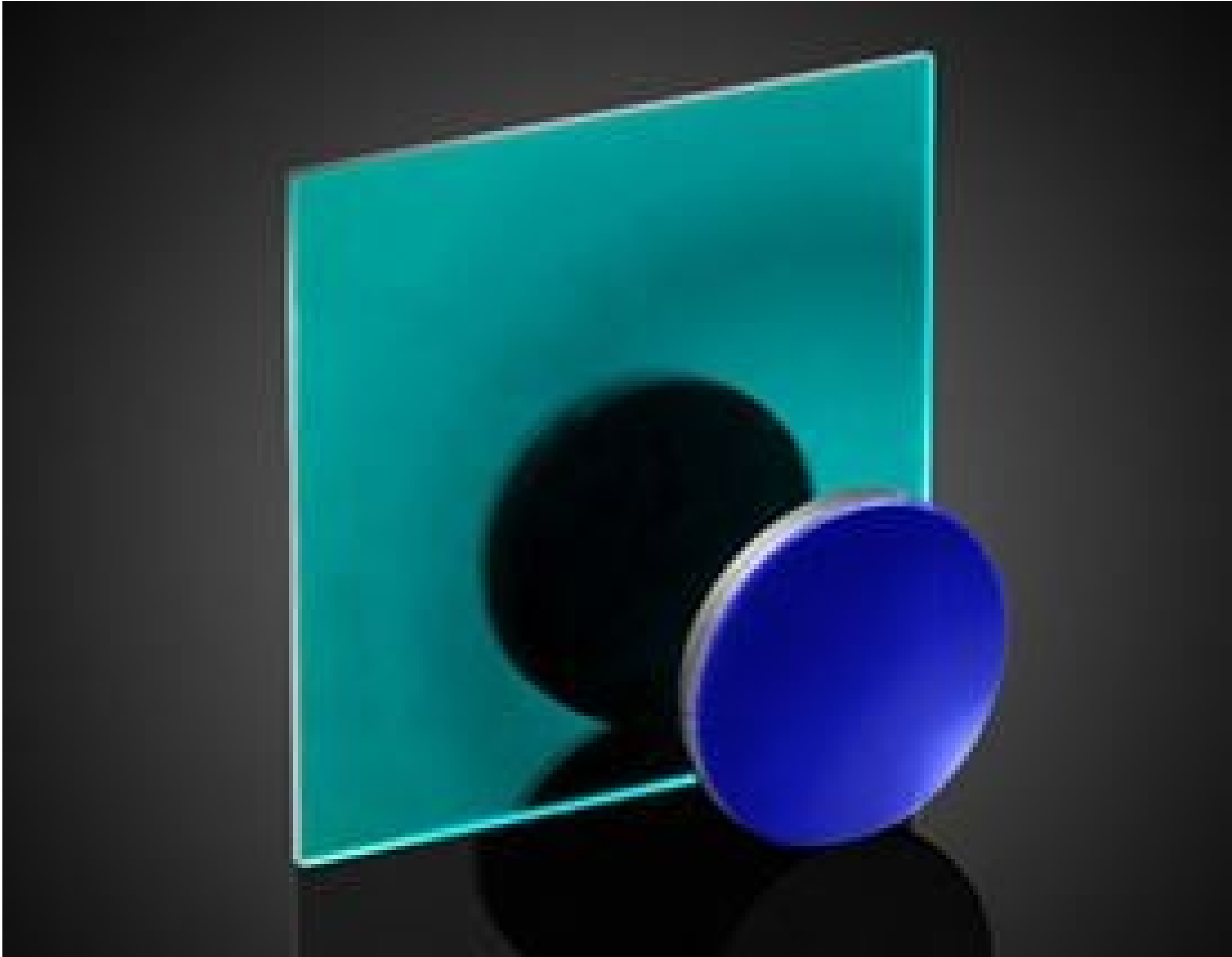

Stock **#14-447** 10 TO 12 DAYS

- 1 + **₹14,790.00**

ADD TO CART

Qty 1-10
₹14,790.00
Qty 11+
₹13,224.00
Volume Pricing
Request Quote

Get Product Downloads

Dimensions (mm):
50.0 x 50.0

Center Wavelength CWL (nm):
500.00

Density (g/cm³):

2.85
Glass/Filter Number: SCHOTT VG20
Length (mm): 50.00
Coating: Uncoated
Color: Green
Index of Refraction n_d: NA
Surface Quality: 60-40
Transformation Temperature (°C): 390
Thickness (mm): 3.00 ±0.2
Type: Bandpass Filter
Wavelength: UV-Vis
Width (mm): 50.00
Bevel: Protective as needed

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View