 



Hoya U360 (UV) 50.8mm Square, Colored Glass Bandpass Filter

See More by [Hoya](#)

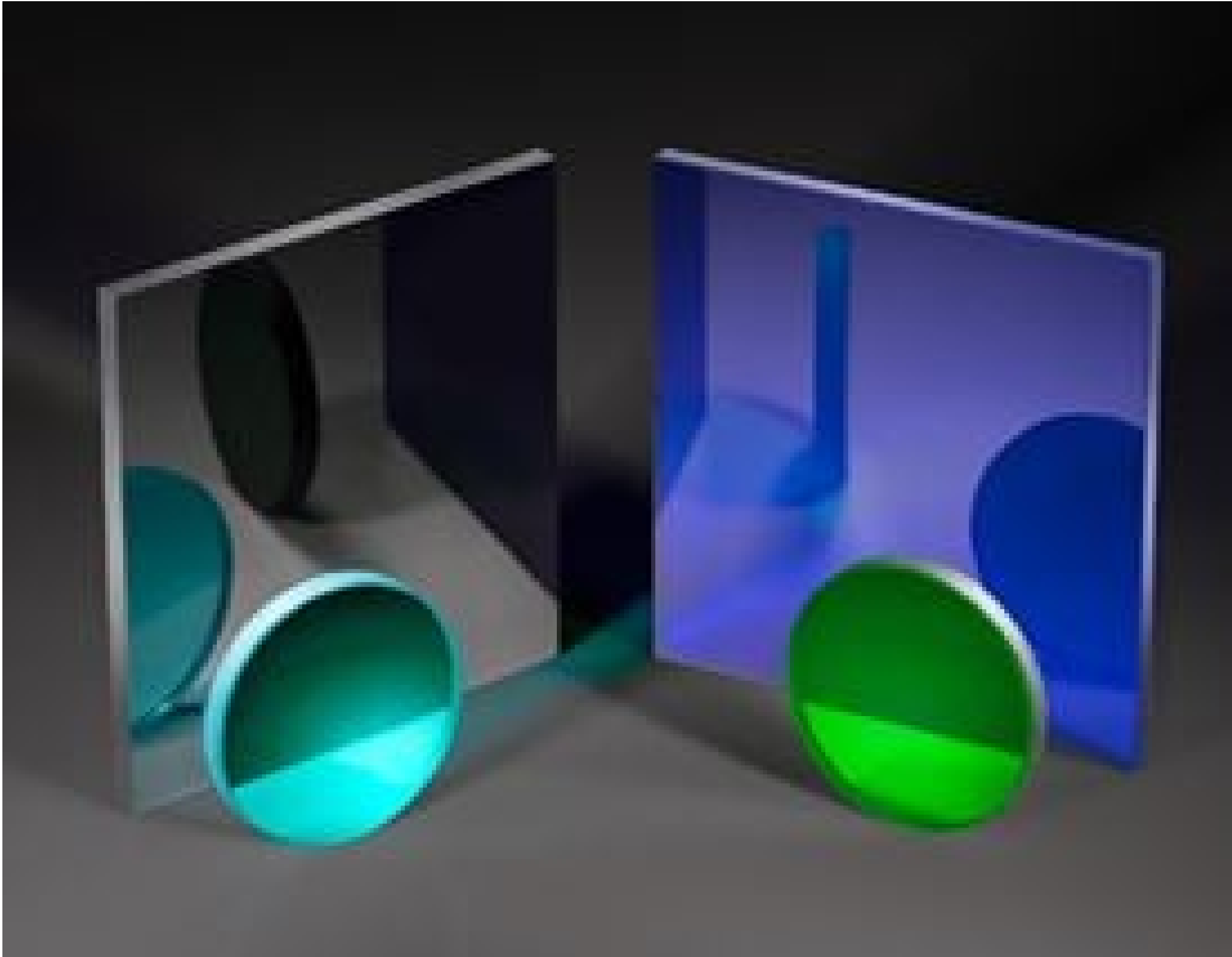

Stock **#46-442** 10 TO 12 DAYS

- 1 + **₹14,703.00**

ADD TO CART

Qty 1-10
₹14,703.00
Qty 11+
₹12,963.00
Volume Pricing
Request Quote

Get Product Downloads



Dimensions (mm):
50.8 x 50.8

Center Wavelength CWL (nm):
360.00

Density (g/cm³): 2.74
Full Width-Half Max FWHM (nm): 45.00
Glass/Filter Number: Hoya U360
Substrate: ☐ Colored Glass
Length (mm): 50.80
Coating: Uncoated
Color: Black
Surface Quality: 60-40
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.2
Type: Bandpass Filter
Wavelength: UV
Width (mm): 50.80
Parallelism (arcmin): ≤2
Dimensional Tolerance (mm): +0/-0.25

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Compliant
Certificate of Conformance: View
