


Variable Frequency Target 5-120 lp/mm

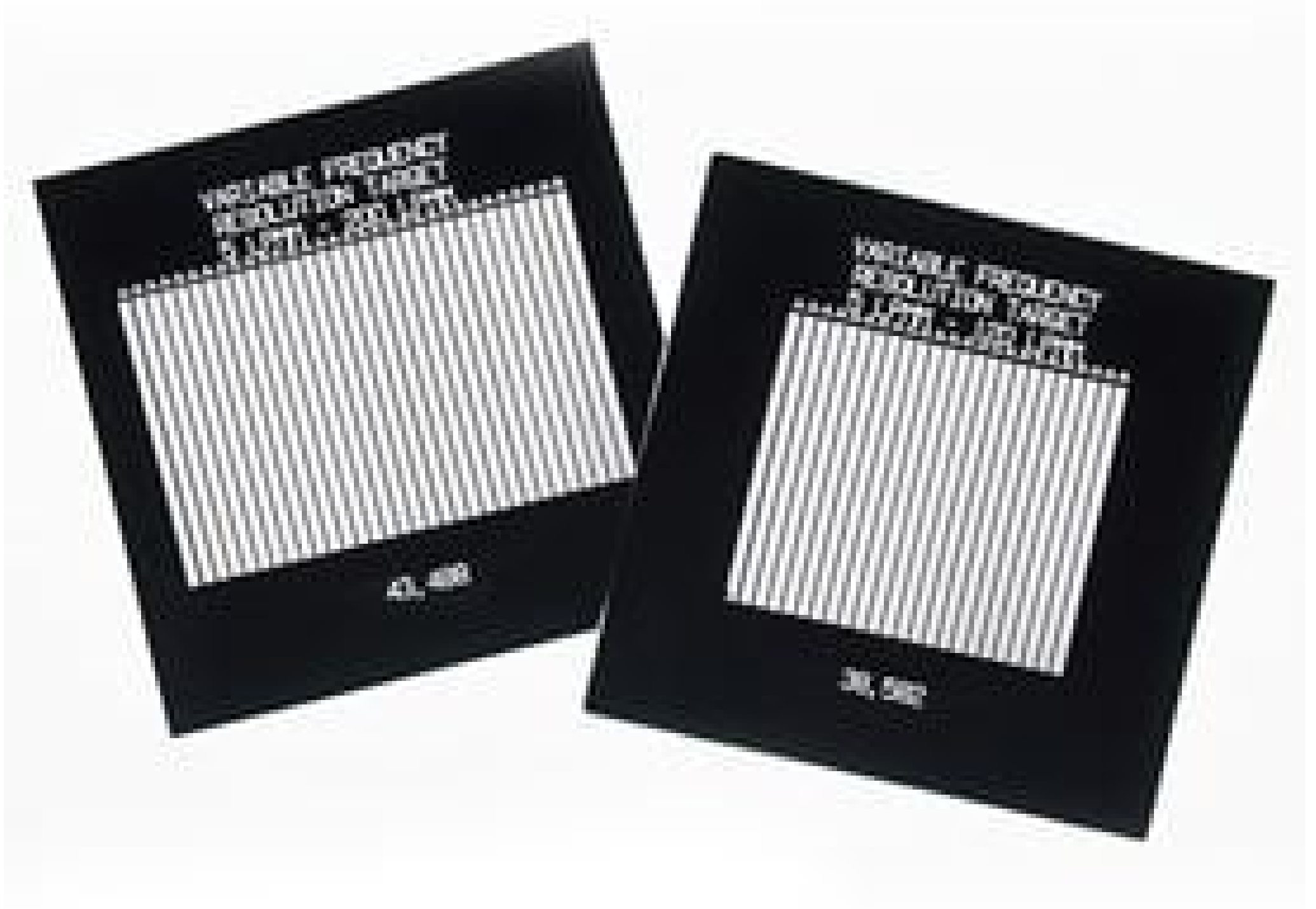

Stock #38-582 CLEARANCE **5 In Stock**

MRP ₹78,689

Price inclusive of all taxes

ADD TO CART

Volume Pricing

Qty 1+	₹78,689 each
Need More?	Request Quote

Product Downloads

Physical & Mechanical Properties

25.4 x 29.85 **Pattern Size (mm):**

2 x 2 **Dimensions (inches):**

1.50 **Thickness (mm):**

Beveled **Edges:**

0.00254 **Flatness (mm):**

Optical Properties

Coating:

Vacuum deposited durable chromium

Substrate:

Float Glass

Optical Density OD (Average):

≥3.0

Surface Quality:

40-10

Regulatory Compliance

RoHS 2015:

[Compliant](#)

Certificate of Conformance:

[View](#)

Reach 240:

[Compliant](#)

Country of Origin:

United States

Imported By:

Edmund Optics India Private Limited
267, Greystone Building, Second Floor,
6th Cross Rd, Binnamangala,
Stage 1, Indiranagar, Bengaluru,
Karnataka, India 560038
Phone: +91- 80-6845 0000

Product Details

- 5 lp/mm to 120 lp/mm or 5 lp/mm to 200 lp/mm
- 1mm Wide Step Size
- 5 lp/mm Step Increments
- Used to Calibrate Video Systems
- Inspect Unknown Resolutions

Variable frequency targets are excellent for evaluating resolution, field distortion, and parfocal stability.