


Variable Frequency Target 5-120 lp/mm

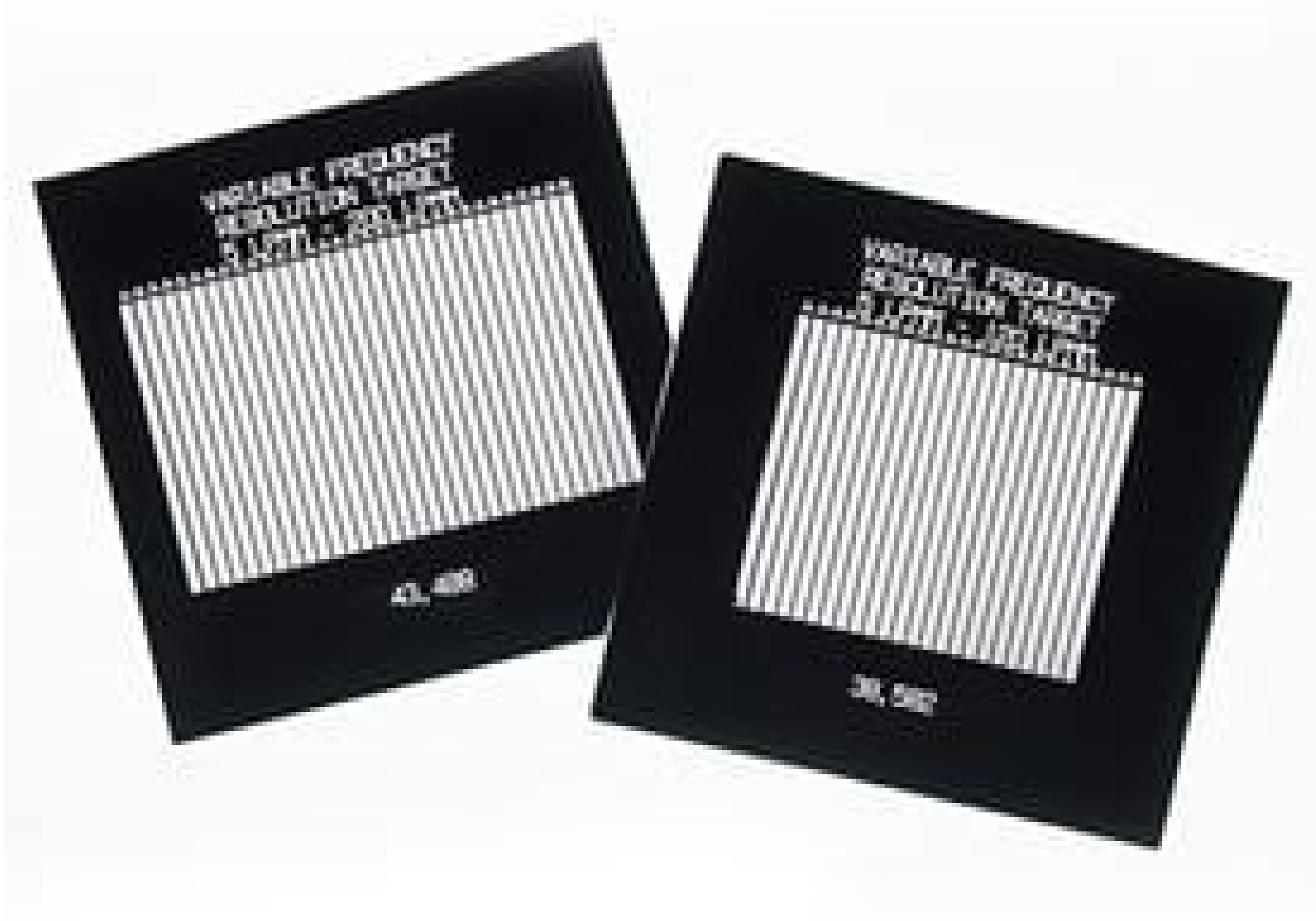

Stock **#38-582** CLEARANCE **8 In Stock**

-

1

+

MRP ₹70,623

Price inclusive of all taxes

ADD TO CART

Volume Pricing	
Qty 1-4	₹70,623 each
Qty 5+	₹67,140 each
Need More?	Request Quote

Product Downloads

Physical & Mechanical Properties	
25.4 x29.85	Pattern Size (mm):
2 x2	Dimensions (inches):
1.50	Thickness (mm):
Beveled	Edges:

0.00254	Flatness (mm):
Optical Properties	
Vacuum deposited durable chromium	Coating:
Float Glass	Substrate:
≥3.0	Optical Density OD (Average):
40-10	Surface Quality:
Regulatory Compliance	
Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 240:
United States	Country of Origin:
Edmund Optics India Private Limited 267, Greystone Building, Second Floor, 6th Cross Rd, Binnamangala, Stage 1, Indiranagar, Bengaluru, Karnataka, India 560038 Phone: +91- 80-6845 0000	Imported By:

Product Details

- 5 lp/mm to 120 lp/mm or 5 lp/mm to 200 lp/mm
 - 1mm Wide Step Size
 - 5 lp/mm Step Increments
 - Used to Calibrate Video Systems
 - Inspect Unknown Resolutions
- Variable frequency targets are excellent for evaluating resolution, field distortion, and parfocal stability.